


Axis interface SPC-AIF-INC

Part number: 537320

FESTO

For connecting a magnetic incremental displacement encoder

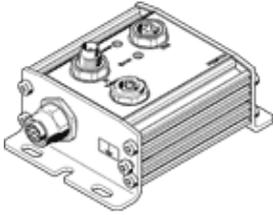

Data sheet

Feature	Value
Max. proportional valve current consumption	1.1 A
Typical axis interface current consumption	60 mA
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Continuous shock resistance per DIN/IEC 68, parts 2 - 82	Tested in accordance with severity level 2
Protection class	IP65 to IEC 60529
Vibration resistance per DIN/IEC 68, parts 2 - 6	Tested in accordance with severity level 2
Ambient temperature	0 ... 50 °C
Product weight	240 g
Electrical connection, proportional valve	Plug socket Round design M9 7-pin
Electrical connection, displacement encoder	8-pin Plug socket M12 Round design
Electrical connection, AIF IN	Plug Round design M9 5-pin
Electrical connection, AIF OUT	Plug socket Round design M9 5-pin