


Sub-base VMPA2-IC-AP-1

Part number: 537981

FESTO

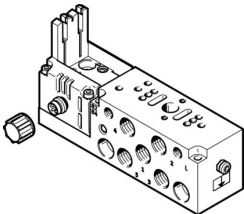

Data sheet

Feature	Value
Width	30.5 mm
Length	107.3 mm
Width dimension	21 mm
Operating pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Certification	c UL us - Recognized (OL)
KC characters	KC EMC
CE marking (see declaration of conformity)	As per EU EMC directive As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	233 g
Electrical connection	M8 Plug
Sub-base mounting type	With through-hole
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Pneumatic connection 3	G1/8
Pneumatic connection 4	G1/8
Pneumatic connection 5	G1/8
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum