


Ball valve actuator unit VZPR-BPD-22-R114

Part number: 540515

FESTO

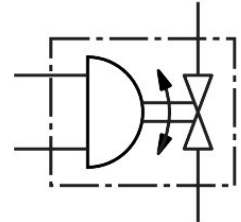

Data sheet

Feature	Value
Structural design	2-way ball valve Quarter turn actuator
Actuation type	Electrical Pneumatic
Mounting position	Any
Type of mounting	CNOMO With internal thread
Fitting connection	Rp1 1/4
Switching position indication	Knob direction = flow direction
Nominal width DN	32
Operating pressure of actuator	1 bar...8.4 bar
Nominal pressure of fitting PN	40
Temperature of medium	-20 °C...150 °C
Ambient temperature	-20 °C...80 °C
LABS (PWIS) conformity	VDMA24364 zone III
Product weight	3200 g
Corrosion resistance class (CRC)	1 - Low corrosion stress