


Shut off valve MS4-EM1-1/4-Z

Part number: 541261

FESTO

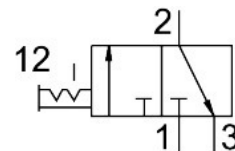

Data sheet

| Feature | Value |
|--|--|
| Structural design | Rotary gate valve |
| Actuation type | Manual |
| Exhaust air function | Without flow control option |
| Type of control | Direct |
| Valve function | 3/2, bistable |
| Operating pressure | 0 MPa...1.4 MPa 0 bar...14 bar |
| C value | 9 l/sbar |
| b-value | 0.39 |
| Standard nominal flow rate | 2200 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Note on materials | RoHS-compliant |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Temperature of medium | -10 °C...60 °C |
| Ambient temperature | -10 °C...60 °C |
| For use in the food industry | See supplementary material information |
| Type of mounting | Line installation With accessories Optionally: |
| Mounting position | Any |
| Flow direction | Non-reversible |
| Product weight | 0.19 kg |
| Pneumatic connection 1 | G1/4 |
| Pneumatic connection 2 | G3/4 |
| Pneumatic connection 3 | G1/4 |
| Seals material | TPE-U(PU) |
| Housing material | Die-cast aluminum |