


Branching module MS12N-FRM-G

Part number: 541682

FESTO

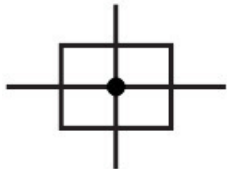

Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Operating pressure	0 bar...20 bar
Standard nominal flow rate in main flow direction 1 -> 2	25000 l/min...42000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C...60 °C
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	3000 g
Pneumatic connection 1	Battery module
Pneumatic connection 2	Battery module
Pneumatic connection 3	2 NPT
Pneumatic connection 4	1 NPT
Housing material	Die-cast aluminum