
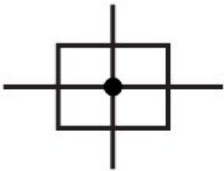


Branching module FRM-Y-D-MAXI

Part number: 542186

FESTO

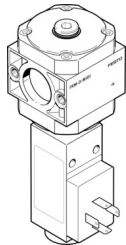

Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Operating pressure	0 MPa...1.2 MPa 0 bar...12 bar
Standard nominal flow rate in main flow direction 1 -> 2	20000 l/min
DC operating voltage range	0 V...125 V
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:::] Inert gas
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	822 g
Pneumatic connection 3	G3/4
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum