


Axial kit
EAMM-A-D40-57A
Part number: 543154

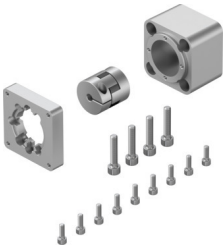

Data sheet

Feature	Value
Nominal length	50.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	6.5 Nm
Product weight	350 g
Interface code, actuator	D40 D40C
Interface code, motor in	57A
Note on materials	RoHS-compliant