


# Vertical pressure supply plate

## VABF-S3-1-P1A3-G14

Part number: 544434

FESTO

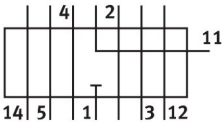

## Data sheet

Feature	Value
Width	26 mm
Based on norm	ISO 15407-1
Mounting position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1
Operating pressure	-0.9 bar...10 bar
Normal nominal flow rate (normalized to DIN 1343)	1000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C...50 °C
Product weight	201 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum