


**Distributor**  
**FCK-3-PK-4-N**  
Part number: 546066

**FESTO**

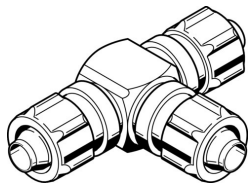

**Data sheet**

Feature	Value
Nominal width	3 mm
Mounting position	Any
Operating pressure for entire temperature range	0 bar...10 bar
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	10 g
Pneumatic connection 1	For barbed fitting, inside diameter 4 mm, with union nut
Pneumatic connection 2	for barbed fitting, inside diameter 3 mm, with nut
Housing material	Wrought aluminum alloy