


**Distributor**  
**FR-8-1/8-BR**  
Part number: 546749

**FESTO**

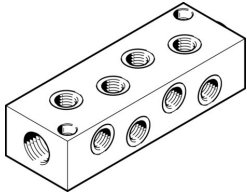

## Data sheet

Feature	Value
Nominal width	8.6 mm
Mounting position	Any
Operating pressure for entire temperature range	0 bar...16 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-:]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
No. of outlets	8
No. of supply lines	1
Pneumatic connection 1	G3/8
Pneumatic connection 2	G1/8
Housing material	Wrought aluminum alloy