


**Sub-base**  
**VMPA2-AP-2-1-EMM-4**  
Part number: 546805

**FESTO**

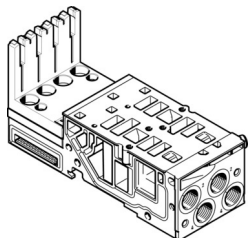

**Data sheet**

| Feature                          | Value                                  |
|----------------------------------|----------------------------------------|
| Width                            | 42 mm                                  |
| Length                           | 107.3 mm                               |
| Width dimension                  | 21 mm                                  |
| Max. no. of valve positions      | 2                                      |
| Operating pressure               | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar |
| Pilot pressure MPa               | 0.3 MPa...0.8 MPa                      |
| Pilot pressure                   | 3 bar...8 bar                          |
| Corrosion resistance class (CRC) | 0 - No corrosion stress                |
| LABS (PWIS) conformity           | VDMA24364-B1/B2-L                      |
| Ambient temperature              | -5 °C...50 °C                          |
| Product weight                   | 210 g                                  |
| Pneumatic connection 2           | G1/8                                   |
| Pneumatic connection 4           | G1/8                                   |
| Note on materials                | RoHS-compliant                         |
| Material of sub-base             | Die-cast aluminum                      |