


# Reducing nipple NPFB-R-G34-G12-MF

Part number: 547837

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

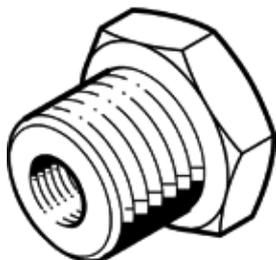

## Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Working pressure	-0.95 ... 40 bar
Operating medium	Compressed air Vacuum
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	44 g
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G1/2
Materials note	Conforms to RoHS