


Cover cap
CPX-M-AK-C
Part number: 548753

FESTO

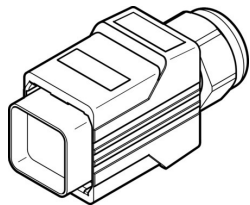

Data sheet

Feature	Value
Width	30 mm
Height	58 mm
Length	22 mm
Certification	UL94 V0
Product weight	54 g
Degree of protection	IP65 IP67 In mounted state as per IEC 60529
Ambient temperature	-5 °C...50 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	Die-cast zinc Nickel-plated
Seals material	NBR
Relative air humidity	5 - 90 % Non-condensing