


# **Plug socket** **MSSD-N**

Part number: 550067

**FESTO**

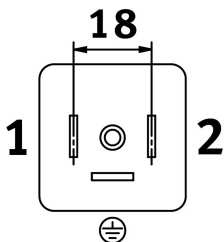

## **Data sheet**

Feature	Value
Based on norm	EN 175301-803
Cable outlet	Angled
Product weight	30 g
Electrical connection 1, design	Rectangular
Electrical connection 1, connection type	Socket
Electrical connection 1, connection technology	Connection diagram form A as per EN 175301-803
Electrical connection 1, number of pins/wires	3
Electrical connection 1, type of mounting	On air solenoid valve with M3 central screw
Electrical connection 2, connection technology	Screw terminal
DC operating voltage range	0 V...24 V
Operating voltage range AC	0 V...250 V
Current rating at 40° C	16 A
Cable fitting	M20x1.5
Cable diameter	8 mm...10 mm
Nominal conductor cross section	1.5 mm <sup>2</sup>
Degree of protection	IP65
Note on degree of protection	In mounted state
Ambient temperature	-25 °C...80 °C
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant
Housing material	PA-reinforced
Housing colour	Black
Material of screws	Steel
Seals material	VMQ