 



Roller lever valve

RWB-3-1/8

Part number: 552432

FESTO

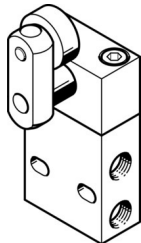

Data sheet

Feature	Value
Valve function	3/2, closed, monostable
Actuation type	Mechanical
Normal nominal flow rate (normalized to DIN 1343)	120 l/min
Pneumatic working port	G1/8
Operating pressure	3.5 bar...8 bar
Structural design	Piston seat
Nominal width	3.5 mm
Type of control	Pilot-controlled
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Actuating force	3.1 N
Product weight	160 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Pneumatic connection 3	G1/8
Seals material	NBR
Housing material	Wrought aluminum alloy Anodized