


Fiber-optic cable
S00C-TB-P-M4-1-R15
Part number: 552825

FESTO

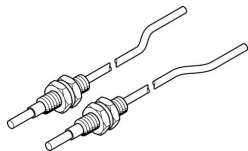

Data sheet

Feature	Value
Note on materials	RoHS-compliant
Method of measurement	Through-beam sensor
Minimum object diameter	0.2 mm
Special feature of fibre-optic cable	Precision
Working range	120 mm
Ambient temperature	-55 °C...70 °C
Head size	M4
Fibre-optic cable length	1 m
Min. bending radius	15 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Housing material	High-alloy stainless steel
Fiber-optic cable	PE
Degree of protection	IP66
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III