


# Vacuum filter

## VAF-DB-3/8

Part number: 553140

FESTO

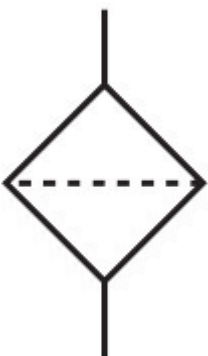

### Data sheet

Feature	Value
Mounting position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 bar...0 bar
Information on operating pressure	Only for use in open vacuum systems
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-5 °C...50 °C
Max. tightening torque	15.3 Nm
Product weight	156 g
Type of mounting	Line installation With wall/surface bracket
Pneumatic connection	G3/8
Vacuum connection	G3/8
Note on materials	RoHS-compliant
Seals material	NBR
Compressed air filter material	PE
Housing material	PP-reinforced
Material of bowl	PA
Ejector pulse suitability	7 bar