


Angled connection plate VABF-S2-2-A1G2-G12

Part number: 555702

FESTO

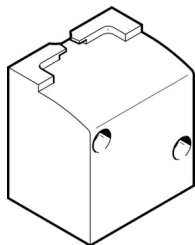

Data sheet

Feature	Value
Width	52 mm
Based on norm	ISO 5599-2
Mounting position	Any
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C...50 °C
Product weight	359 g
Type of mounting	With through-hole
Note on materials	RoHS-compliant
Housing material	Wrought aluminum alloy