


Angled connection plate VABF-S2-2-A1G2-N12

Part number: 555703

FESTO

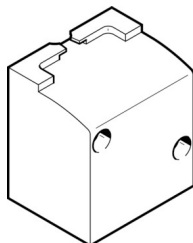

Data sheet

| Feature | Value |
|--|--|
| Width | 58.1 mm |
| Based on norm | ISO 5599-2 |
| Mounting position | Any |
| Operating pressure | -0.09 MPa...1 MPa -0.9 bar...10 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC) | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Degree of protection | IP65 NEMA 4 |
| Ambient temperature | -5 °C...50 °C |
| Product weight | 359 g |
| Type of mounting | With through-hole |
| Note on materials | RoHS-compliant |
| Housing material | Wrought aluminum alloy |