
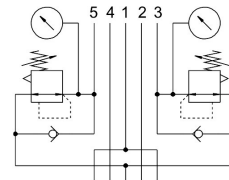


# Regulator plate VABF-S1-2-R5C2-C-6

Part number: 555765

**FESTO**

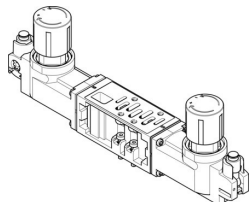

## Data sheet

| Feature                                  | Value                                                              |
|------------------------------------------|--------------------------------------------------------------------|
| Width                                    | 54 mm                                                              |
| Based on norm                            | ISO 5599-1                                                         |
| Mounting position                        | Any                                                                |
| Pneumatic vertical stacking              | Pressure regulator for 2 and 4, reversible                         |
| Controller function                      | Outlet pressure constant<br>With secondary exhausting              |
| Optional pressure gauge                  | Possible                                                           |
| Pressure regulation range MPa            | 0.05 MPa...0.6 MPa                                                 |
| Pressure regulation range                | 0.5 bar...6 bar                                                    |
| Pressure regulation range psi            | 7.25 psi...87 psi                                                  |
| Inlet pressure 1                         | 0.5 bar...10 bar                                                   |
| Inlet pressure 1 MPa                     | 0.05 MPa...1 MPa                                                   |
| Inlet pressure 1 psi                     | 7.25 psi...145 psi                                                 |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 0 - No corrosion stress                                            |
| LABS (PWIS) conformity                   | VDMA24364-B1/B2-L                                                  |
| Degree of protection                     | IP65<br>NEMA 4                                                     |
| Ambient temperature                      | -5 °C...50 °C                                                      |
| Product weight                           | 1990 g                                                             |
| Vertical stacking mounting type          | On manifold sub-base<br>On individual sub-base                     |
| Pressure gauge connection                | With retaining clamp                                               |
| Note on materials                        | RoHS-compliant                                                     |
| Material of operator panel               | PA                                                                 |
| Controller housing material              | Die-cast aluminum                                                  |