


Clevis foot LSN-80

Part number: 5565

FESTO

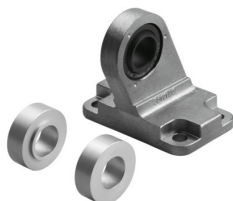

Data sheet

Feature	Value
Size	80
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...120 °C
Max. load capacity	6 kN
Product weight	753 g
Note on materials	RoHS-compliant
Mounting material	Spherulitic graphite iron
Bushing material	Wrought aluminum alloy
Rod end bearing material	Steel PTFE