


Clevis foot LSN-100

Part number: 5566

FESTO

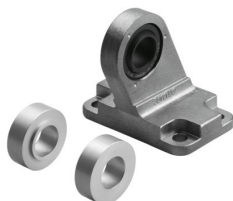

Data sheet

Feature	Value
Size	100
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...120 °C
Max. load capacity	9 kN
Product weight	1169 g
Note on materials	RoHS-compliant
Mounting material	Spherulitic graphite iron
Bushing material	Wrought aluminum alloy
Rod end bearing material	Steel PTFE