


**Connecting cable**  
**VMPAL-KM-S-SD25-IP67-5**  
Part number: 560420

**FESTO**

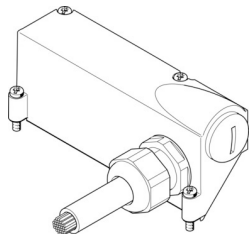

**Data sheet**

Feature	Value
Product weight	1195 g
Electrical connection	Cable with plug
Cable length	5 m
Cable characteristic	Standard
Min. cable bending radius	122 mm
Cable diameter	10.2 mm
Cable design	25 x 0.34 mm <sup>2</sup>
Degree of protection	IP67 as per IEC 60529
Ambient temperature with flexible cable installation	-5 °C...80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	PVC