


# Power supply module VMPAL-SP-QS3/8"

Part number: 560953

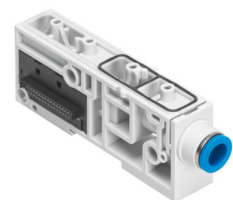

## Data sheet

| Feature                          | Value                                      |
|----------------------------------|--------------------------------------------|
| Width                            | 23.2 mm                                    |
| Length                           | 107.3 mm                                   |
| Integrated function              | With electrical manifold module            |
| Valve manifold design            | Valve sizes can be mixed                   |
| Operating pressure               | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar     |
| Pilot pressure MPa               | 0.3 MPa...0.8 MPa                          |
| Pilot pressure                   | 3 bar...8 bar                              |
| Corrosion resistance class (CRC) | 3 - High corrosion stress                  |
| LABS (PWIS) conformity           | VDMA24364-B1/B2-L                          |
| Ambient temperature              | -5 °C...50 °C                              |
| Product weight                   | 50 g                                       |
| Pneumatic connection 1           | For pneumatic tubing outside diameter 3/8" |
| Note on materials                | RoHS-compliant                             |
| Power supply module material     | Wrought aluminum alloy<br>PA-reinforced    |