


Power supply module VMPAL-SP-QS1/2"

Part number: 560954

FESTO

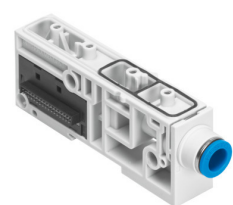

Data sheet

Feature	Value
Width	23.2 mm
Length	107.3 mm
Integrated function	With electrical manifold module
Valve manifold design	Valve sizes can be mixed
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	50 g
Pneumatic connection 1	For pneumatic tubing outside diameter 1/2"
Note on materials	RoHS-compliant
Power supply module material	Wrought aluminum alloy PA-reinforced