


Axial kit
EAMM-A-P4-28B-40A
Part number: 562637

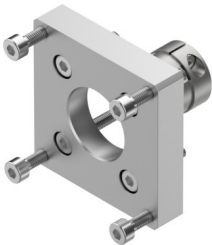

Data sheet

Feature	Value
Nominal length	8.3 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	0.28 kgmm ²
Transferable torque	0.7 Nm
Product weight	50 g
Interface code, actuator	P4-28B
Interface code, motor in	40A
Interface code, coupling housing	28B
Note on materials	RoHS-compliant