


Solenoid coil VACC-S13-18-A1-1

Part number: 562889

FESTO

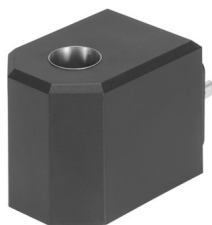

Data sheet

Feature	Value
Actuation type	Electrical
Mounting position	Any
Switching position indication	no
Duty cycle	100%
Insulation class	H
Coil characteristics	24 V DC: 2.1 W
Permissible voltage fluctuations	-15 % / +10 %
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	-20 °C...60 °C
Product weight	210 g
Electrical connection	Form A Plug as per EN 175301-803
Note on materials	RoHS-compliant
Solenoid coil material	PA UP