


# Throttle plate

## VABF-S7-F1B1P2-F

Part number: 563395

FESTO

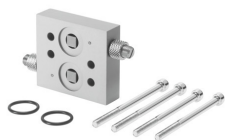

### Data sheet

Feature	Value
Mounting position	Any
Pilot air supply port	External Internal
Operating pressure	0 MPa...1.2 MPa 0 bar...12 bar
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Type of mounting	With through-hole
Pilot air port 12	G1/4
Pneumatic connection 1	G1/4
Pneumatic connection 2	Flange 1/4 NAMUR connection diagram
Pneumatic connection 3	G1/4
Note on materials	RoHS-compliant
Material of sub-base	Aluminum, ematal coated
Seals material	NBR