 



End plate VMPAL-EPL-SD9-IP40

Part number: 570777

FESTO

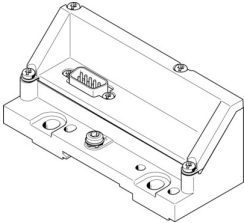

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. no. of valve positions	8
Valve manifold design	Valve sizes can be mixed
Max. no. of solenoid coils	8
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP40
Note on degree of protection	In mounted state
Ambient temperature	-5 °C...50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum PA-reinforced