


# Fixed flow restrictor-SET VMPA1-FT-NW0.3-1.7

Part number: 572543

FESTO

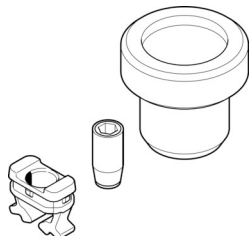

## Data sheet

| Feature                                              | Value                                                              |
|------------------------------------------------------|--------------------------------------------------------------------|
| Valve function                                       | Flow control function                                              |
| Pneumatic connection 1                               | Sub-base                                                           |
| Standard nominal flow rate in flow control direction | 3.5 l/min...115 l/min                                              |
| Operating pressure                                   | -0.9 bar...10 bar                                                  |
| Ambient temperature                                  | -5 °C...60 °C                                                      |
| Nominal width                                        | 0.3 mm...1.7 mm                                                    |
| Mounting position                                    | Any                                                                |
| Operating medium                                     | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media             | Operation with oil lubrication possible (required for further use) |
| LABS (PWIS) conformity                               | VDMA24364-B1/B2-L                                                  |
| Storage temperature                                  | -20 °C...40 °C                                                     |
| Temperature of medium                                | -5 °C...60 °C                                                      |
| Note on materials                                    | RoHS-compliant                                                     |
| Retaining bracket material                           | POM                                                                |
| Hollow bolt material                                 | Wrought aluminum alloy                                             |