


Manifold rail
VABM-L1-14G-G14-20-GR
Part number: 573498

FESTO

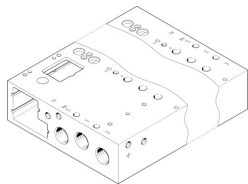

Data sheet

Feature	Value
Width dimension	16 mm
Mounting position	Any
Max. no. of valve positions	20
Certification	c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...60 °C
Product weight	2655 g
Pilot air port 12/14	M5
Pilot exhaust air port 82/84	M5
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy