


Push-in L-fitting, long QBMLL-M5-5/32-U-M

Part number: 574303

FESTO

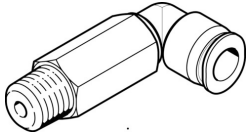

Data sheet

Feature	Value
Size	Standard
Nominal width	0.098 in
Type of seal on screwed plug	Sealing ring
Design	L-shape, long
Pack size	0
Operating pressure for entire temperature range	0.095 MPa...1 MPa 0.95 bar...10 bar 13.775 psi...145 psi
Maritime classification	See certificate
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	0 °C...60 °C
Nominal tightening torque	0.5 Nm
Tolerance for nominal tightening torque	± 10%
Product weight	0.282 oz
Type of mounting	External hexagon, AF 8
Pneumatic connection 1	External thread M5
Pneumatic connection 2	for pneumatic tubing outside diameter 5/32 "
Ambient temperature Fahrenheit	32 °F...140 °F
Releasing ring color	Gray
Note on materials	RoHS-compliant
Housing material	PBT
Material of threaded seal	NBR
Releasing ring material	POM
Material of tube retaining claw	High-alloy stainless steel