


Plug
NECU-S1W9-C2-ACO
Part number: 574588

FESTO

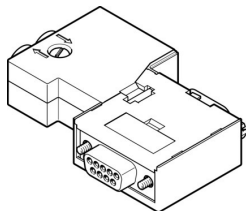

Data sheet

Feature	Value
Type of mounting	4-40 UNC-2B
Product weight	59 g
Fieldbus interface	Sub-D, 9-pin, socket
Electrical connection 1	Socket, Sub-D, 9-pin
Electrical connection 2	Screw terminal, can be shielded
Baud rate	1 Mbit/s
Approved cable diameter	8 mm 8 mm
Connection cross section	0.14 mm ² ...0.5 mm ²
Degree of protection	IP20
Ambient temperature	-20 °C...70 °C
Relative air humidity	75 % at 25 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	PC-reinforced