


Vertical pressure exhaust plate

VABF-L1-P7A13-M7

Part number: 574594

FESTO

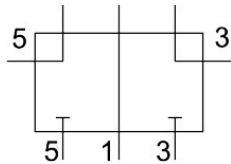

Data sheet

Feature	Value
Width dimension	10.5 mm
Max. no. of valve positions	1
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Certification	RCM compliance mark c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection 3	M7
Pneumatic connection 5	M7
Note on materials	RoHS-compliant
Plate material	Wrought aluminum alloy