


Sub-base
VMPAC-AP-14-SP-1
Part number: 576576

FESTO

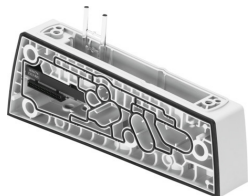

Data sheet

Feature	Value
Width	32.8 mm
Length	169 mm
Width dimension	26.8 mm
Max. no. of valve positions	1
Operating pressure	-0.9 bar...8 bar
Pilot pressure	3 bar...8 bar
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-5 °C...50 °C
Product weight	160 g
Pneumatic connection 1	G1/4
Pneumatic connection 2	G $\frac{1}{4}$
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Housing material	PA-reinforced