


# T quick connector TCK-1/4-PK-4-KU

Part number: 6265

FESTO

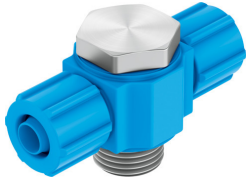

## Data sheet

Feature	Value
Nominal width	3.4 mm
Type of seal on screwed plug	Sealing edge
Mounting position	Any
Design	T-shape
Pack size	10
Operating pressure for entire temperature range	-0.095 MPa...1 MPa -0.95 bar...10 bar -13.775 psi...145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Pneumatic connection 1	External thread G1/4
Pneumatic connection 2	for pneumatic tubing outside diameter 6 mm for barbed fitting, inside diameter 4 mm, with nut
Material of union nut	POM
Note on materials	RoHS-compliant
Housing material	POM
Hollow bolt material	Wrought aluminum alloy, anodized
Swivel joint material	POM