


# AND gate ZK-PK-3

Part number: 6685

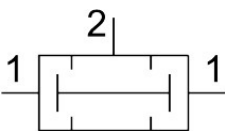

## Data sheet

Feature	Value
Valve function	AND function
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Type of mounting	With through-hole
Standard nominal flow rate	120 l/min
Operating pressure	1.6 bar...8 bar
Ambient temperature	-10 °C...60 °C
Housing material	Brass POM
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Nominal width	2.4 mm
Mounting position	Any
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-10 °C...60 °C
Product weight	10 g
Pneumatic connection 3	PK-3
Note on materials	RoHS-compliant
Seals material	NBR