


Manifold rail
VABM-L1-18W-G38-24-M-G
Part number: 8004926

FESTO

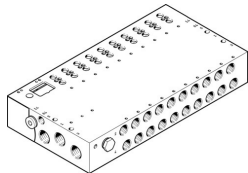

Data sheet

Feature	Value
Width dimension	19 mm
Mounting position	Any
Max. no. of valve positions	24
Certification	c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...60 °C
Product weight	4909 g
Pilot air port 12/14	G1/8
Pilot exhaust air port 82/84	G1/8
Pneumatic connection 1	G3/8
Pneumatic connection 2	G1/4
Pneumatic connection 3	G3/8
Pneumatic connection 4	G1/4
Pneumatic connection 5	G3/8
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy