


Supply plate VABF-B10-30-P1A4-G38

Part number: 8026434

FESTO

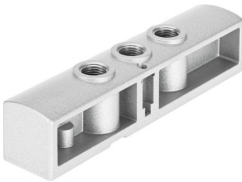

Data sheet

Feature	Value
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	6 Nm
Product weight	167 g
Type of mounting	With through-hole
Pneumatic connection 1	G3/8
Pneumatic connection 3	G3/8
Pneumatic connection 5	G3/8
Note on materials	RoHS-compliant
Supply plate material	Die-cast aluminum