


# End plate VABE-S1-1R-G12

Part number: 8032670

**FESTO**

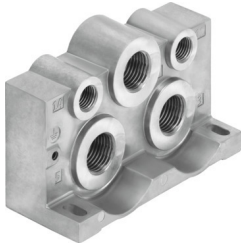

## Data sheet

| Feature                                    | Value  |
|--|--|
| Width                                      | 44 mm  |
| Exhaust air function                       | Via throttle plate   |
| Based on norm                              | ISO 5599-1   |
| Operating pressure                         | 0 MPa...1 MPa<br>0 bar...10 bar                                    |
| Suitability for vacuum                     | yes  |
| CE marking (see declaration of conformity) | As per EU low voltage directive                                    |
| Operating medium                           | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media   | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)           | 0 - No corrosion stress  |
| LABS (PWIS) conformity                     | VDMA24364-B1/B2-L  |
| Storage temperature                        | -20 °C...60 °C   |
| Temperature of medium                      | -10 °C...50 °C   |
| Pilot medium                               | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Ambient temperature                        | -10 °C...50 °C   |
| Product weight                             | 410 g  |
| Type of mounting                           | with through-hole for M6 screw                                     |
| Pneumatic connection 1                     | G1/2   |
| Pneumatic connection 3                     | G1/2   |
| Pneumatic connection 5                     | G1/2   |
| Note on materials                          | RoHS-compliant   |
| End plate material                         | Die-cast aluminum  |