
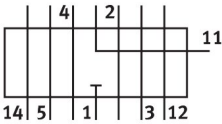


# Vertical pressure supply plate

## VMPA2-VSP-QS1/4

Part number: 8035442

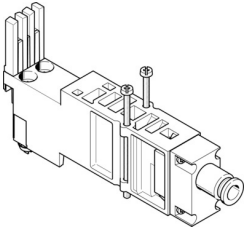

### Data sheet

| Feature                          | Value                                         |
|----------------------------------|-----------------------------------------------|
| Width dimension                  | 21 mm                                         |
| Operating pressure               | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar        |
| Pilot pressure MPa               | 0.3 MPa...0.8 MPa                             |
| Pilot pressure                   | 3 bar...8 bar                                 |
| Operating medium                 | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress                      |
| LABS (PWIS) conformity           | VDMA24364-B1/B2-L                             |
| Ambient temperature              | -5 °C...50 °C                                 |
| Product weight                   | 80 g                                          |
| Pneumatic connection 1           | QS-1/4                                        |
| Note on materials                | RoHS-compliant                                |
| Supply plate material            | PA-reinforced                                 |