


# Parallel kit EAMM-U-145-D80-126AA-188

Part number: 8059069

FESTO

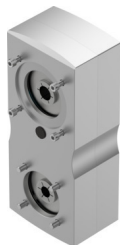

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Size                     | 145                    |
| Mounting position        | Any                    |
| Max. rotational speed    | 4000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C...60 °C         |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C...60 °C         |
| Mass moment of inertia   | 2270 kgmm <sup>2</sup> |
| No-load driving torque   | 2 Nm                   |
| Transferable torque      | 9.5 Nm                 |
| Product weight           | 12000 g                |
| Interface code, actuator | D80                    |
| Interface code, motor in | 126AA                  |
| Note on materials        | RoHS-compliant         |