


**Vacuum filter**  
**OAFF-G3-5**  
Part number: 8068944

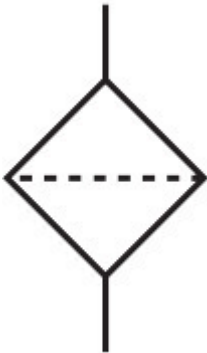

**Data sheet**

| Feature                        | Value                                                       |
|--------------------------------|-------------------------------------------------------------|
| Grade of filtration            | 40 µm                                                       |
| Pack size                      | 10                                                          |
| Operating pressure             | -95 kPa...0 kPa<br>-0.95 bar...0 bar<br>-13.775 psi...0 psi |
| Operating medium               | Atmospheric air based on ISO 8573-1:2010 [7:::-]            |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L                                           |
| Product weight                 | 1 g                                                         |
| Type of mounting               | Push-on<br>Engaging                                         |
| Note on materials              | RoHS-compliant                                              |
| Compressed air filter material | Fabric<br>PA                                                |
| Housing material               | POM                                                         |
| Ejector pulse suitability      | 0.7 MPa<br>7 bar<br>101.5 psi                               |