
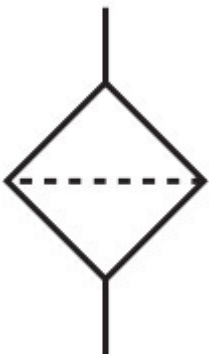


Vacuum filter
OAFF-G3-7
Part number: 8068945

FESTO

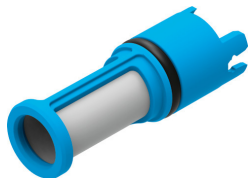

Data sheet

Feature	Value
Grade of filtration	40 µm
Pack size	10
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	1.5 g
Type of mounting	Push-on Engaging
Note on materials	RoHS-compliant
Seals material	NBR
Compressed air filter material	Fabric PA
Housing material	POM
Ejector pulse suitability	0.7 MPa 7 bar 101.5 psi