


# Ball valve actuator unit VZBM-A-3/4"-RP-25-D-2-B2-PA10

Part number: 8070237

**FESTO**

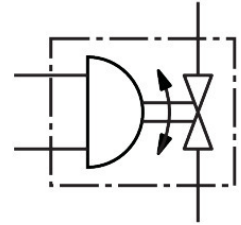

## Data sheet

Feature	Value
Structural design	2-way ball valve Quarter turn actuator
Actuation type	Pneumatic
Mounting position	Any
Type of mounting	Line installation
Fitting connection	Rp3/4
Switching position indication	Slot direction = flow direction
Nominal width DN	20
Operating pressure	5.5 bar...8 bar
Nominal pressure of fitting PN	25
Medium	Compressed air as per ISO 8573-1:2010 [:-:~:] Inert gas Water – no water vapor Neutral liquids
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Dew point min. 10 °C below the ambient temperature and temperature of medium Operation with oil lubrication possible (required for further use)
Temperature of medium	-15 °C...90 °C
Ambient temperature	-20 °C...80 °C
Flow rate Kv	28 m³/h
Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364 zone III
Housing material	Brass, nickel-plated
Material number of housing	CW617N
Seals material	FPM HNBR PTFE
Ball material	Brass, chrome-plated
Material number for ball	CW614N
Shaft material	Brass
Material number for shaft	CW614N

<b>Feature</b>	<b>Value</b>
Product weight	1287 g
Corrosion resistance class (CRC)	1 - Low corrosion stress