


**Manifold rail**  
**VABM-P6-15M-G18-M5-6**  
Part number: 8083545

**FESTO**

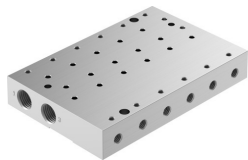

**Data sheet**

| Feature                                   | Value                         |
|-------------------------------------------|-------------------------------|
| Width dimension                           | 15 mm                         |
| Structural design                         | Connection direction at side  |
| Max. no. of valve positions               | 6                             |
| Corrosion resistance class (CRC)          | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity                    | VDMA24364-B2-L                |
| Max. tightening torque for valve mounting | 0.6 Nm                        |
| Product weight                            | 210 g                         |
| Pneumatic connection 1                    | G1/8                          |
| Pneumatic connection 2                    | M5                            |
| Note on materials                         | RoHS-compliant                |
| Manifold rail material                    | Wrought aluminum alloy        |