


Axial kit
EAMM-A-P5-28B-40RA
Part number: 8107712

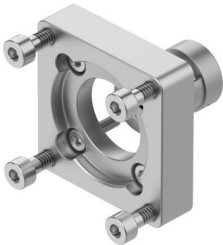

Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transferable torque	1.1 Nm
Product weight	49 g
Interface code, actuator	P5-28B
Interface code, motor in	40RA
Note on materials	RoHS-compliant