


**Sub-base**  
**VABS-K2-10B-16-U14-P**  
Part number: 8122826

**FESTO**

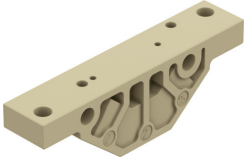

**Data sheet**

| Feature                                   | Value   |
|---|---|
| Size                                      | 10  |
| Nominal width                             | 1.6 mm  |
| Fluid connector                           | Internal thread 1/4-28 UNF-2B                                     |
| Mounting position                         | Any   |
| Structural design                         | Connection direction downwards                                    |
| Max. no. of valve positions               | 1   |
| Flow direction                            | Non-reversible  |
| Operating medium                          | Liquid media<br>Gaseous media                                     |
| Information on operating and pilot media  | Observe resistance of materials that come into contact with media |
| Corrosion resistance class (CRC)          | 0 - No corrosion stress   |
| LABS (PWIS) conformity                    | VDMA24364 zone III  |
| Storage temperature                       | -20 °C...70 °C  |
| Temperature of medium                     | 0 °C...50 °C  |
| Ambient temperature                       | 0 °C...50 °C  |
| Max. tightening torque for valve mounting | 0.2 Nm  |
| Product weight                            | 7 g   |
| Sub-base mounting type                    | With through-hole   |
| Pneumatic valve mounting type             | With internal thread  |
| Note on materials                         | RoHS-compliant  |
| Material of sub-base                      | PEEK  |