


Pneumatic valve
VOFC-L-M52-M-FN14-FN
Part number: 8122930

FESTO

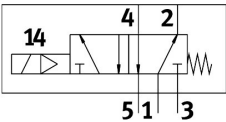

Data sheet

Feature	Value
Operating pressure	0.25 MPa...0.8 MPa 2.5 bar...8 bar 36.25 psi...116 psi
Degree of protection	IP65
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant