


Pneumatic valve

VOFC-LT-M32C-M-FN14-FN

Part number: 8122932

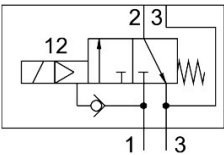

Data sheet

Feature	Value
Standard nominal flow rate	601 l/min
Operating pressure	0 MPa...0.8 MPa 0 bar...8 bar 0 psi...116 psi
Degree of protection	IP65
Certificate issuing authority	TÜV 968/V 1251.00/24
Safety function	Safe venting
Safety integrity level (SIL)	Up to SIL 3 high demand mode Up to SIL 3 low demand mode
Information on operating pressure	0 – 0.8 bar with external pilot air
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant